


Elbow fitting NPFC-L-R12-G12-MF

Part number: 8030219

FESTO

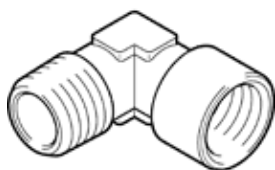

Data sheet

Feature	Value
Material threaded fitting	Nickel-plated brass
Container size	10
Working pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-20 ... 150 °C
Product weight	77.8 g
Pneumatic connection, port 1	R1/2
Pneumatic connection, port 2	G1/2
Materials note	Conforms to RoHS