


**Y-fitting**  
**NPFC-Y-R12-2G12-MFF**  
Part number: 8030234

**FESTO**

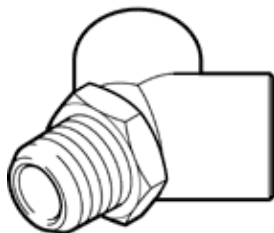

**Data sheet**

<b>Feature</b>	<b>Value</b>
Material threaded fitting	Nickel-plated brass
Container size	10
Working pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [---]
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-20 ... 150 °C
Product weight	138.5 g
Pneumatic connection, port 1	R1/2
Pneumatic connection, port 2	G1/2
Materials note	Conforms to RoHS