


Push-in fitting NPQH-D-G14-S8-P10

Part number: 578364

FESTO

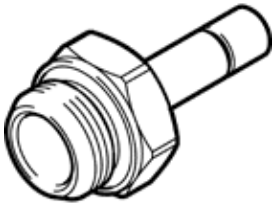

Data sheet

Feature	Value
Size	Standard
Nominal size	6 mm
Type of seal on screw-in stud	Sealing ring
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 20 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	3 - High corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	0 ... 150 °C
Max. tightening torque	15 Nm
Product weight	14.8 g
Pneumatic connection, port 1	Male thread G1/4
Pneumatic connection, port 2	Push-in sleeve QS-8
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material of threaded seal	FPM
Material release ring	Nickel-plated brass