


# Coupling plug KS3-CK-6

Part number: 3478

FESTO

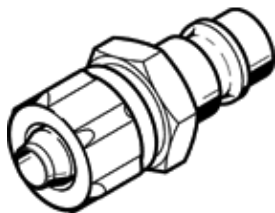

## Data sheet

Feature	Value
Nominal size	4.9 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	378 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	21 g
Pneumatic connection, port 1	CK-6
Materials note	Conforms to RoHS