


# Socket connector NTSD-GD-9

Part number: 18493

FESTO

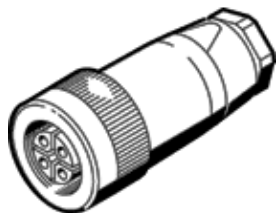

## Data sheet

Feature	Value
Mounting type	With sleeve nut
Assembly position	Any
Product weight	25 g
Electrical connection	Plug socket, straight Screwed terminal 4-pin
Operating voltage range AC	$\leq 250$ V
Permissible current load	16 A
Cable gland connection	Pg9
Permissible cable diameter	6 ... 8 mm
Terminal cross-section	1.5 mm <sup>2</sup>
Protection class	IP67
Ambient temperature	-5 ... 50 °C
Storage temperature	-20 ... 70 °C
Material housing	PBT
Material electrical contact	Copper alloy Brass