


Illuminating seal MEB-LD-12-24DC

Part number: 151717

FESTO

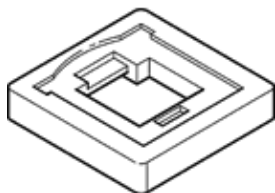

Data sheet

Feature	Value
Switching position indicator	LED
Mounting type	On solenoid valve with M2.5 central screw
Product weight	0.6 g
Electrical connection	Rectangular design, MSEB Per DIN EN 175301-803 Plug pattern type C to EN 175301-803
Operating voltage range DC	12 ... 24 V
Protective earth connection	Available
Nominal power, illuminating seal	0.05 W
Protection class	IP65
Ambient temperature	-25 ... 85 °C
Material housing	TPE-U(PU)