


# Suction cup complete VASB-55-1/4-SI-B

Part number: 1373812

FESTO

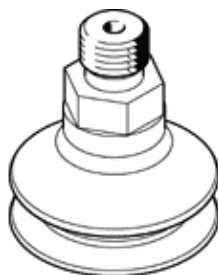

## Data sheet

Feature	Value
Suction cup height compensator	20 mm
Nominal size	4 mm
suction cup diameter	55 mm
suction cup volume	30.4 cm <sup>3</sup>
Position of connection	on top
Assembly position	Any
Suction cup shape	Round, bellows 1.5 conv
Working pressure	-0.95 ... 0 bar
Nominal working pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-40 ... 200 °C
Retention force at nominal operating pressure	110 N
Product weight	29 g
Mounting type	Via vacuum port
Vacuum connection	G1/4
Color	transparent
Shore hardness	60 +/- 5
Material of threaded plug	Wrought Aluminum alloy
Materials note	Contains PWIS substances Conforms to RoHS
Material suction cup	VMQ (silicon)