 



Suction cup complete VASB-40-1/4-PUR-B

Part number: 1395691

FESTO

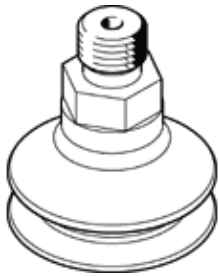

Data sheet

Feature	Value
Suction cup height compensator	13.7 mm
Nominal size	4 mm
suction cup diameter	40 mm
suction cup volume	11.11 cm ³
Effective suction diameter	34.4 mm
Position of connection	on top
Assembly position	Any
Suction cup shape	Round, bellows 1.5 conv
Working pressure	-0.95 ... 0 bar
Nominal working pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Ambient temperature	-20 ... 60 °C
Retention force at nominal operating pressure	60 N
Product weight	30 g
Mounting type	Via vacuum port
Vacuum connection	G1/4
Color	blue
Shore hardness	60 +/- 5
Material of threaded plug	Zinc die-casting
Materials note	Conforms to RoHS
Material suction cup	PUR