


I/O module
CP-E08-M12-CL
Part number: 538787

FESTO

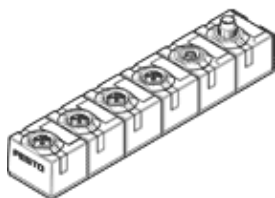

Data sheet

Feature	Value
ATEX category Gas	II 3G
Explosion ignition protection type Gas	Ex nA IIC T6 X Gc
ATEX category Dust	II 3D
Explosion ignition protection type Dust	Ex tc IIIC T70°C X Dc IP67
Explosion-proof ambient temperature	-5°C ≤ Ta ≤ +50°C
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU-Ex protection guideline (ATEX)
Corrosion resistance classification CRC	1 - Low corrosion stress
Authorization	C-Tick c UL us - Listed (OL)