 



Clamping module EV-20/120-5

Part number: 13292

FESTO

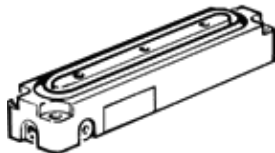

Data sheet

Feature	Value
Stroke	5 mm
Clamping surface	20x120
Assembly position	Any
Mode of operation	single-acting
Working pressure	2 ... 6 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Ambient temperature	-20 ... 40 °C
Product weight	190 g
Mounting type	with through hole
Pneumatic connection	M5
Materials note	Free of copper and PTFE
Material housing	Aluminum die cast
Material membrane	TPE-U(PU)