 



# Clamping module EV-32-5

Part number: 150685

FESTO

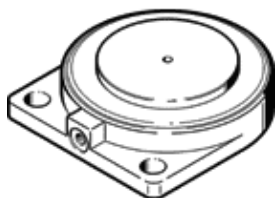

## Data sheet

Feature	Value
Stroke	5 mm
Clamping surface	Ø 32
Assembly position	Any
Mode of operation	single-acting
Working pressure	<= 6 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Ambient temperature	-10 ... 40 °C
Product weight	34 g
Mounting type	with through hole
Pneumatic connection	M3
Materials note	Free of copper and PTFE
Material housing	Aluminum die cast
Material membrane	TPE-U(PU)