
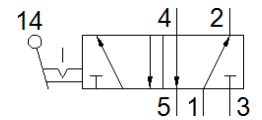


# Hand lever valve

## H-5-1/4-B

Part number: 8995

FESTO

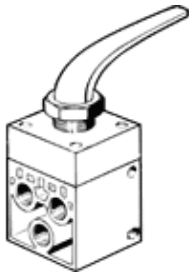

## Data sheet

| Feature                      | Value             |
|------------------------------|-------------------|
| Valve function               | 5/2 bistable      |
| Standard nominal flow rate   | 550 l/min         |
| Working pressure             | -0.95 ... 10 bar  |
| Design structure             | Poppet seat       |
| Nominal size                 | 7 mm              |
| Type of piloting             | direct            |
| Ambient temperature          | -10 ... 60 °C     |
| Actuating force              | 2 N               |
| Product weight               | 510 g             |
| Mounting type                | with through hole |
| Pneumatic connection, port 1 | G1/4              |
| Pneumatic connection, port 2 | G1/4              |
| Pneumatic connection, port 3 | G1/4              |
| Pneumatic connection, port 4 | G1/4              |
| Pneumatic connection, port 5 | G1/4              |
| Material seals               | NBR               |
| Material housing             | Aluminum die cast |