 



# Pneumatic valve J-5-PK-3

Part number: 4503

FESTO

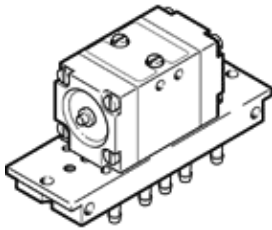

## Data sheet

Feature	Value
Valve function	5/2 bistable
Standard nominal flow rate	105 l/min
Working pressure	1 ... 8 bar
Design structure	Poppet seat
Nominal size	2.5 mm
Switching time reversal	9 ms
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Ambient temperature	0 ... 60 °C
Product weight	130 g
Mounting type	Optional On subbase On mounting frame with through hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Pneumatic connection, port 3	PK-3
Pneumatic connection, port 4	PK-3
Pneumatic connection, port 5	PK-3
Materials note	Conforms to RoHS
Material of connecting plate	Brass PPS-reinforced
Material seals	NBR
Material housing	Plastic Zinc die-casting