


# Plug base MHAP-PI

Part number: 197260

FESTO

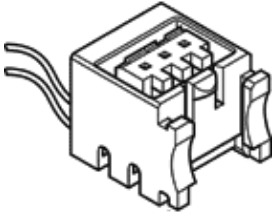

## Data sheet

Feature	Value
Mounting type	Clip
Assembly position	Any
Product weight	4 g
Electrical connection	Plug socket 2-pin
Operating voltage range DC	$\leq 60$ V
Permissible current load	3 A
Cable length	0.5 m
Cable diameter	1 mm
Cable structure	2x0,14
Protection class	IP40
Ambient temperature	-20 ... 80 °C
Ambient temperature with flexible cable installation	-20 ... 50 °C
Materials note	Conforms to RoHS
Material housing	PA
Material electrical contact	Copper Galvanized