 



OR gate OS-1/8-B

Part number: 6681

FESTO

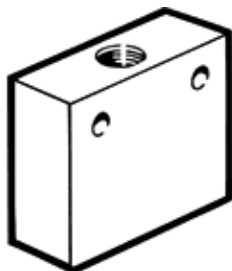

Data sheet

Feature	Value
Valve function	OR function
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Mounting type	with through hole
Standard nominal flow rate	500 l/min
Working pressure	1 ... 10 bar
Ambient temperature	-10 ... 60 °C
Material housing	Wrought Aluminum alloy
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Nominal size	4 mm
Assembly position	Any
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Medium temperature	-10 ... 60 °C
Product weight	45 g
Pneumatic connection, port 3	G1/8
Materials note	Conforms to RoHS
Material seals	NBR