


Ball valve QH-1/2

Part number: 9543

FESTO

with hand lever.

This type is suitable for vacuum.

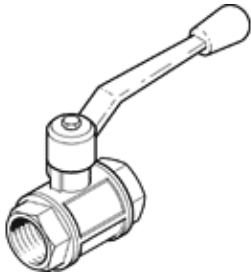

Data sheet

Feature	Value
Valve function	2/2 bistable
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/2
Type of actuation	manual
Mounting type	Line installation
Standard nominal flow rate	11,500 l/min
Nominal size	15 mm
Ambient temperature	-20 ... 180 °C
Material housing	Brass
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water
Sealing principle	soft
Design structure	Ball valve
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)