

# 5224-2I

## Brand Features

With Leviton's extensive assortment of combination devices, you can fill a one-gang space with two switches, a switch and receptacle, even a switch and GFCI. From sensor guide lights to multi-purpose styles and Tamper-Resistant receptacles, we accommodate your every need. These devices come in a range of colors and are backed by a limited two-year warranty. Built to last and designed to save space, these attractively styled devices are at home in any setting.

## Item Description

15 Amp, 120/277 Volt, Duplex Style Single-Pole / Single-Pole AC Combination Switch, Commercial Grade, Grounding, Side Wired, - Ivory

## Technical Information

### AC Horsepower Ratings

**HP Rating:** 1/2HP-120V 2HP-240V-277V

**Max. Amperage:** 12 Amp

### Electrical Specifications

**Dielectric Voltage:** Withstands 1500V for 1 minute

**Grounding:** Grounding

**Overload UL20 Test:** 100 cycles of OL at 4.8 times rated current

**Switch Amperage:** 15 Amp

**Switch Voltage:** 120/277V AC

**Temperature Rise:** Maximum 30 degrees C rise

### Environmental Specifications

**Flammability:** Rated V-2 per UL 94

**Operating Temperature:** -40°C to 65°C

### Material Specifications

**Actuator Material:** Thermoplastic

**Body Material:** Thermoplastic

**Color:** Ivory

**Strap Material:** Steel

### Mechanical Specifications

**Product ID:** Stamped on Strap

**Terminal Accom.:** 14-12 AWG

**Terminal ID:** Brass-Hot Black-Hot White-Neutral Green-Gnd

**Termination:** Side

**Torque Range:** 12-14 inch pounds

### Product Features

**Color:** Ivory

**HP Rating:** 1/2HP-120V 2HP-240V-277V

**Warranty:** 2-Year Limited

### Standards and Certifications

**ANSI:** C-73

**CSA C22.2 No. 111:** File #152105

**NEMA:** WD-1 & WD-6

**NOM:** 057

**UL Standard:** UL 20

**Warranty:** 2-Year Limited




Color:  Ivory

UPC Code: 07847722645

Country Of Origin: Mexico

## Dimensional Diagram

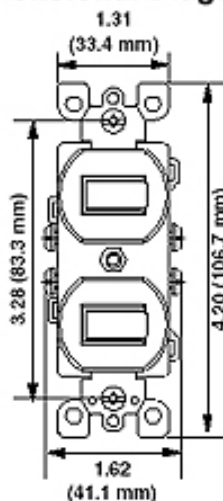

## SPECIFICATION SUBMITTAL

JOB NAME: <input type="text"/>	CATALOG NUMBERS: <input type="text"/>	
JOB NUMBER: <input type="text"/>	<input type="text"/>	<input type="text"/>

**Leviton Manufacturing Co., Inc.**

201 North Service Road, Melville, NY 11747

Teléfono: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): +1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

**Visit our Website at: [www.leviton.com](http://www.leviton.com)**

© 2018 Leviton Manufacturing Co., Inc. Todos los derechos reservados. Subject to change without notice.

**Leviton has a global presence.**

If you would like to know where your local Leviton office is located please go to:

[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

