 



Compressed air reservoir CRVZS-0.1

Part number: 160233

FESTO

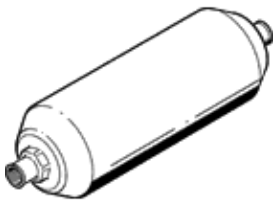

Data sheet

Feature	Value
Volume	0,1 l
Assembly position	Any
Conforms to standard	AD 2000 reference sheet
Working pressure	-0.95 ... 16 bar
Certificate issuing department	TSSACRN0H17477.5C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-] Nitrogen
Corrosion resistance classification CRC	3 - High corrosion stress
Food-safe	See Supplementary material information
Medium temperature	-10 ... 100 °C
Ambient temperature	-10 ... 100 °C
Authorization	CRN TÜV
Max. tightening torque, connecting thread	15 Nm
Product weight	226 g
Mounting type	Fixing clips
Pneumatic connection	G1/8
Materials note	Free of copper and PTFE Conforms to RoHS
Material of air reservoir	High alloy steel, non-corrosive
Material fixing clips	High alloy steel, non-corrosive