


Push-in connector NPQP-D-Q6-S10-FD-P10

Part number: 133136

FESTO

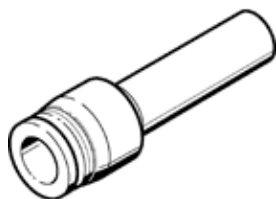

Data sheet

Feature	Value
Size	Standard
Nominal size	3.8 mm
Container size	10
Design structure	Push/pull principle
Temperature dependent working pressure	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	4 - Very high corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Product weight	3.6 g
Pneumatic connection, port 1	Push-in sleeve QS-10
Pneumatic connection, port 2	For tubing outside diameter 6 mm
Materials note	Contains PWIS substances Conforms to RoHS
Material housing	PP
Material of tube retaining claw	High alloy steel, non-corrosive