



# Hand Tools



## RZR Series Cable Shears

**1253105**

- For cutting copper and aluminium cables
- Not suitable for steel wire and wire ropes

Forged in Germany



CODE NO	mm	Ømm	
1253105	170 - 6-1/2"	15	6

**1253109**  
**Bent Long Nose Pliers**  
 (Polished Finish/DuoTech Handles)  
 DIN / TS ISO 5745



Suitable for cutting soft and hard wire, special tool steel, polished finish (electrofilm), softgrip handles

CODE NO	mm	Ømm	
1253109	200 - 8"	1.6	6

**12531 Series**  
**Water Pump Pliers**  
 (Box Joint/PVC Sleeves)  
 DIN ISO 8976



9-position adjustment, box-joint design, Chrome Vanadium steel, phosphate finish, PVC sleeves

CODE NO	mm	max. mm	
1253103	250 - 10"	28	6
1253104	300 - 12"	35	6

**1253101**  
**6 Piece Screwdriver Set - Slotted/Phillips**



CODE NO	
1253101	1

- Slotted 3.0x75, 4.0x100, 5.5x125, 6.5x150 mm
- Phillips PH1x80, PH2x100 mm

**1253102**  
**6 Piece Screwdriver Set - Slotted/Pozidriv**



CODE NO	
1253102	1

- Slotted 3.0x75, 4.0x100, 5.5x125, 6.5x150 mm
- Pozidriv PZ1x80, PZ2x100 mm



**12530 Series**  
**Insulated Slotted Screwdrivers**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 2380



For live working up to 1000V AC or 1500V DC, Chrome Vanadium Molybdenum steel blade (phosphate finish), softgrip handle

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm	mm	
1253078	2.5	75	12
1253079	3.0	100	12
1253080	3.5	100	12
1253081	4.0	100	12
1253082	5.5	125	12
1253083	6.5	150	12

**12530 Series**  
**Insulated Terminal (Pozidriv/Slotted) Screwdrivers**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 8764



For terminal screws (Pozidriv/Slotted), ideal for live working up to 1000V AC or 1500V DC, Chrome Vanadium Molybdenum steel blade (phosphate finish), softgrip handle

**Individually tested as per DIN EN 60900: 2004 norm**

CODE NO		mm	
1253088	MOD1	80	12
1253089	MOD2	100	12

**1253071**  
**Insulated Power Diagonal Cutters**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 5749



Ideal for live working up to 1000V AC or 1500V DC, suitable for cutting all wires (incl. piano wire), special tool steel, chrome finish, softgrip handles

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm	mm	
1253071	180 - 7"	2.0	6

**12530 Series**  
**Insulated Phillips Screwdrivers**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 8764



For live working up to 1000V AC or 1500V DC, Chrome Vanadium Molybdenum steel blade (phosphate finish), softgrip handle

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO		mm	
1253084	PH1	80	12
1253085	PH2	100	12

**12530 Series**  
**Insulated Combination Pliers**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 5746



Ideal for live working up to 1000V AC or 1500V DC, suitable for cutting soft and hard wire, special tool steel, chrome finish, softgrip handles

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm	mm	
1253065	160 - 6"	1.8	6
1253066	180 - 7"	2.0	6
1253067	200 - 8"	2.5	6

**12530 Series**  
**Insulated Long Nose Pliers**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 5745



Ideal for live working up to 1000V AC or 1500V DC, suitable for cutting soft and hard wire, special tool steel, chrome finish, softgrip handles

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm	mm	
1253072	160 - 6"	1.6	6
1253073	200 - 8"	1.6	6

**12530 Series**  
**Insulated Pozidriv Screwdrivers**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 8764



For live working up to 1000V AC or 1500V DC, Chrome Vanadium Molybdenum steel blade (phosphate finish), softgrip handle

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO		mm	
1253086	PZ1	80	12
1253087	PZ2	100	12

**12530 Series**  
**Insulated Diagonal Cutters**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 5749



Ideal for live working up to 1000V AC or 1500V DC, suitable for cutting soft and hard wire, special tool steel, chrome finish, softgrip handles

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm	mm	
1253068	140 - 5-1/2"	1.8	6
1253069	160 - 6"	2.0	6
1253070	180 - 7"	2.5	6

**1253074**  
**Insulated Bent Long Nose Pliers**  
(VDE Approved)

VDE 0682 Teil 201, DIN ISO 5745



Ideal for live working up to 1000V AC or 1500V DC, suitable for cutting soft and hard wire, special tool steel, chrome finish, softgrip handles

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm	mm	
1253074	200 - 8"	1.6	6

■ **1253075**  
**Insulated Wire Stripping Pliers**  
 (VDE Approved)  
 VDE 0682 Teil 201



Ideal for live working up to 1000V AC or 1500V DC, for stripping the plastic insulation of single and multi-strand conductors, special tool steel, chrome finish, softgrip handles  
**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm "	mm <sup>2</sup>	
1253075	160 - 6"	10	6

■ **1253094**  
**2 Piece Insulated Pliers Set (VDE Approved)**



CODE NO	
1253094	1

- 180 mm Combination Pliers
- 160 mm Diagonal Cutters

■ **1253095**  
**3 Piece Insulated Pliers Set (VDE Approved)**



CODE NO	
1253095	1

- 180 mm Combination Pliers
- 160 mm Diagonal Cutters
- 160 mm Long Nose Pliers

■ **1253096**  
**5 Piece Insulated Pliers and Screwdriver Sets (VDE Approved)**



CODE NO	
1253096	1

- 180 mm Combination Pliers
- 160 mm Diagonal Cutters
- Slotted 4x100, 5.5x125 mm
- Pozidriv P22x100 mm

■ **12530 Series**  
**9 Piece Insulated Pliers and Screwdriver Sets (VDE Approved-in Vinyl Wallet)**



CODE NO	
1253097	1

- 180 mm Combination Pliers
- 160 mm Diagonal Cutters
- 160 mm Long Nose Pliers
- Slotted 2.5x75, 4x100, 5.5x125 mm
- Phillips PH1x80 mm, PH2x100 mm
- Voltage Tester, Long

1253098	1
---------	---

- 180 mm Combination Pliers
- 160 mm Diagonal Cutters
- 160 mm Long Nose Pliers
- Slotted 2.5x75, 4x100, 5.5x125 mm
- Pozidriv P21x80, P22x100 mm
- Voltage Tester, Long

■ **1253076**  
**Insulated Water Pump Pliers**  
 VDE 0682 Teil 201, DIN ISO 8976



Ideal for live working up to 1000V AC or 1500V DC, 9-position adjustment, box-joint design, Chrome Vanadium steel, phosphate finish, softgrip handles  
**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm "	max. mm	
1253076	250 - 10"	28	6

■ **1253077**  
**RZR Series Insulated Cable Shears (VDE Approved)**



Ideal for live working up to 1000V AC or 1500V DC, for cutting copper and aluminum cables, special tool steel, phosphate finish, softgrip handles

**Not suitable for steel wire and wire ropes**

**Individually tested as per DIN EN 60900: 2012 norm**

CODE NO	mm "	mm	
1253077	170 - 6-1/2"	15	6

**COLD IMPACT RESISTANCE (-25°C)**

**ELECTRICAL TEST (10.000V)**

**PRESSURE TEST (5000V)**

**INSULATION ADHESION TEST**

**FLAMMABILITY TEST**

**10.000V TEST (%100 Control)**



**12530 Series**  
**12 Piece Insulated Pliers and**  
**Screwdriver Sets (VDE Approved-in Vinyl Wallet)**




CODE NO	1
1253099	1

- 180 mm Combination Pliers
- 160 mm Diagonal Cutters
- 160 mm Long Nose Pliers
- Automatic Wire Stripper
- Slotted 2.5x75, 4x100, 5.5x125 mm
- Phillips PH1x80, PH2x100 mm
- Voltage Tester, Long
- Trimming Knife Trapezoid Blade 19 mm
- Compact Tape Measures 3mx16mm

1253100	1
---------	---

- 180 mm Combination
- 160 mm Diagonal Cutters
- 160 mm Long Nose Pliers
- Automatic Wire Stripper
- Slotted 2.5x75, 4x100, 5.5x125 mm
- Pozidriv PH1x80, PH2x100 mm
- Voltage Tester, Long
- Trimming Knife Trapezoid Blade 19 mm
- Compact Tape Measures 3m x 16mm

**1253092**  
**4 Piece Insulated Screwdriver Set**  
**(VDE Approved) - Slotted/Phillips**

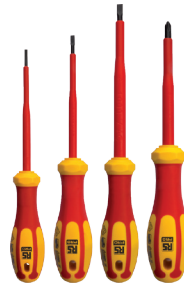

CODE NO	1
1253092	1

- Slotted 2.5x75, 4.0x100, 5.5x125,
- Phillips PH2x100 mm

**1253093**  
**4 Piece Insulated Screwdriver Set**  
**(VDE Approved) - Slotted/Pozidriv**



CODE NO	1
1253093	1

- Slotted 2.5x75, 4.0x100, 5.5x125 mm
- Phillips PZ2x100 mm

**1253106**  
**6 Piece Electronics Screwdriver Set -**  
**Slotted/Phillips**



CODE NO	1
1253106	1

- Slotted 1.5x40, 2.0x60, 2.5x80, 3.0x80 mm
- Phillips PH00x60, PH0x60 mm

**1253108**  
**6 Piece Electronics Screwdriver Set - TORX**



CODE NO	1
H99-04-06	1


- Torx T5x40, T6x40, T7x40, T8x40, T9x60, T10x60

**1253107**  
**6 Piece Electronics Screwdriver Set -**  
**Slotted/Phillips**



CODE NO	1
1253107	1

- Slotted 1.5x40, 2.0x60, 2.5x80, 3.0x80 mm
- Phillips PH00x60, PH0x60 mm

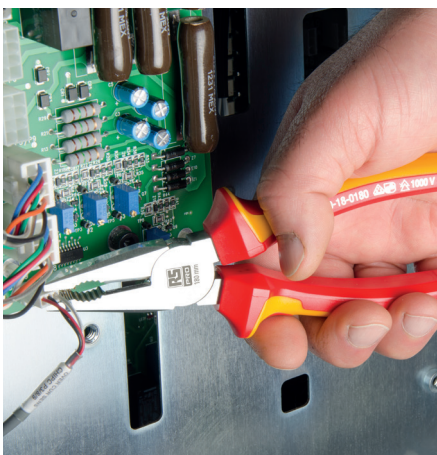

**12530 Series**  
**Rethreading Tools**



For cleaning out and cutting damaged threads in electrical boxes, precision ground HSS tap, softgrip handle

CODE NO	M SIZE	mm	12
1253090	M3.5x0.6	118	12
1253091	M4.0x0.7	118	12



# Hand Tools

