 



Suction cup complete VASB-100-1/4-NBR

Part number: 35416

FESTO

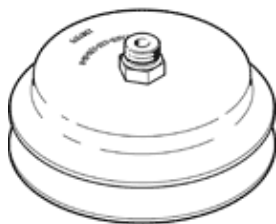

Data sheet

Feature	Value
Nominal size	4 mm
suction cup diameter	100 mm
Effective suction diameter	85 mm
Position of connection	on top
Suction cup shape	Round, bellows 1.5 conv
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Ambient temperature	-20 ... 80 °C
Breakaway force at 70% vacuum	397 N
Retention force at nominal operating pressure	397 N
Mounting thread	G1/4
suction cup mounting	G 1/4
Vacuum connection	G1/4
Color	Black
Shore hardness	60 +/- 5
Material of threaded plug	Zinc die-casting
Materials note	Conforms to RoHS
Material suction cup	NBR