


Push-in/threaded L-fitting, long QBMLL-M5-1/8-U-M

Part number: 574302

FESTO

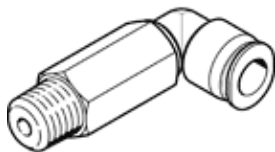

Data sheet

Feature	Value
Size	Standard
Nominal size	0.098 "
Type of seal on screw-in stud	Sealing ring
Operating pressure complete temperature range	0 ... 145 Psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	32 ... 140 °F
Authorization	Germanischer Lloyd
Nominal tightening torque	0.5 Nm
Tolerance for nominal tightening torque	± 10 %
Product weight	0.282 oz
color of release ring	Grey
Materials note	Conforms to RoHS
Material housing	PBT
Material of threaded seal	NBR
Material release ring	POM
Material of tube retaining claw	High alloy steel, non-corrosive