


# Fiber-optic cable SOOC-DS-H-M6-1-R40

Part number: 552841

FESTO

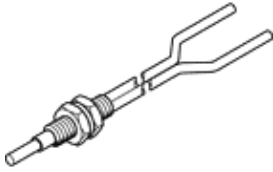

## Data sheet

Feature	Value
Materials note	Contains PWIS substances
Measurement method	Diffuse reflection sensor
Minimal object diameter	0.1 mm
Fiber-optic cable - special feature	Large working range
Working range	200 mm
Ambient temperature	-55 ... 70 °C
Size, head	M6
Fiber optic cable length	1 m
Min. bending radius	40 mm
Max. tightening torque	3 Nm
Outside diameter	2.2 mm
Material housing	Brass Nickel plated
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress