


Fiber-optic cable SOOC-DS-M6-1-R25

Part number: 552838

FESTO

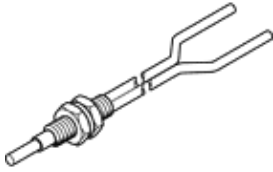

Data sheet

Feature	Value
Materials note	Contains PWIS substances
Measurement method	Diffuse reflection sensor
Minimal object diameter	0.1 mm
Fiber-optic cable - special feature	Standard
Working range	140 mm
Ambient temperature	-55 ... 70 °C
Size, head	M6
Fiber optic cable length	1 m
Min. bending radius	25 mm
Max. tightening torque	3 Nm
Outside diameter	2.2 mm
Material housing	High alloy steel, non-corrosive
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress