


# Non-return valve H-M5

Part number: 3671

FESTO

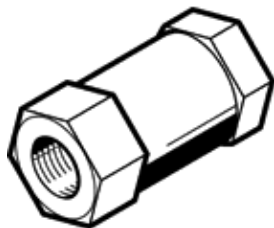

## Data sheet

Feature	Value
Valve function	Non-return function
Pneumatic connection, port 1	M5
Pneumatic connection, port 2	M5
Mounting type	Line installation
Standard nominal flow rate	115 l/min
Working pressure	0.4 ... 8 bar
Ambient temperature	-10 ... 60 °C
Material housing	Brass
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Medium temperature	-10 ... 60 °C
Materials note	Conforms to RoHS
Material seals	NBR