


# Socket connector cable KMPV-SUB-D-15-10

Part number: 177674

FESTO

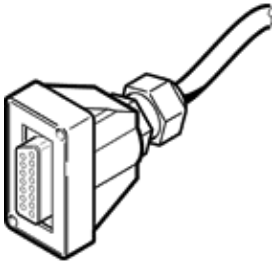

## Data sheet

Feature	Value
Mounting type	with through hole
Assembly position	Any
Product weight	400 g
Electrical connection	Plug socket Sub-D 15-pin
Operating voltage range DC	$\leq 30$ V
Permissible current load	2.8 A
Cable length	10 m
Cable diameter	8.2 mm
Cable structure	15x0,25
Protection class	IP65
Ambient temperature	-20 ... 80 °C
Material cable sheath	PUR
Material housing	PBT-reinforced
Material electrical contact	Copper alloy Gold plated