 



# Differential pressure valve LRL-1/8-NPT-QS-5/32-U

Part number: 190904

FESTO

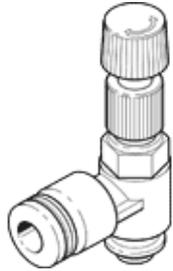

## Data sheet

Feature	Value
Controller function	Differential pressure, constant
Pneumatic connection, port 1	NPT1/8-27
Mounting type	Threaded
Inlet pressure 1	0 ... 9 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Assembly position	Any
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Product weight	19 g
Material of threaded plug	Brass
Materials note	Conforms to RoHS