 



Differential pressure valve LRL-10-32-UNF-QS-5/32-U

Part number: 190903

FESTO

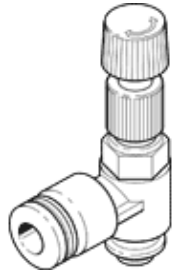

Data sheet

Feature	Value
Controller function	Differential pressure, constant
Pneumatic connection, port 1	UNF10-32
Mounting type	Threaded
Inlet pressure 1	0 ... 9 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Assembly position	Any
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Product weight	9 g
Material of threaded plug	Brass
Materials note	Conforms to RoHS