

Contact insert module - HC-M-RJ45-AD-PC-M - 1419885


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Contact insert module, number of positions: RJ45, type : RJ45, Pin, 50 V, 1 A, application: Data, with adapter for patch cables



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 253237
GTIN	4055626253237

Technical data

Dimensions

Height	50.7 mm
Width	34.2 mm
Length	14.6 mm

Electrical characteristics

Note	Use the patch cable from the accessories list.
Rated voltage (III/3)	50 V
Rated current	1 A
Rated surge voltage	0.8 kV
Connection profile	RJ45
Transmission characteristics (category)	CAT6

Ambient conditions

Ambient temperature (operation)	-25 °C ... 60 °C
---------------------------------	------------------

Mechanical characteristics

Insertion/withdrawal cycles	≥ 500
-----------------------------	-------

General

Type	RJ45
------	------

Contact insert module - HC-M-RJ45-AD-PC-M - 1419885

Technical data

General

Series	HC-M-RJ45
Color	light gray
Number of module slots	1
Flammability rating according to UL 94	V0
Degree of pollution	3
Overvoltage category	III

Material data

Contact material	Copper alloy
Contact surface material	Au
Contact carrier material	PC

Standards and Regulations


Flammability rating according to UL 94	V0
--	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

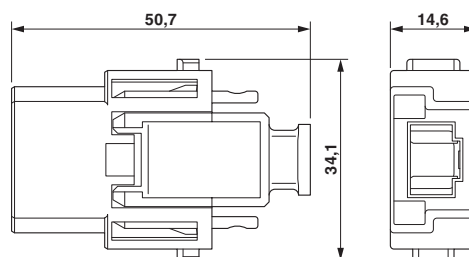

Male insert

Approvals

Approvals

Approvals




CSA / UL Recognized / EAC

Ex Approvals

Approval details

Contact insert module - HC-M-RJ45-AD-PC-M - 1419885

Approvals

CSA		http://www.csagroup.org/services-industries/product-listing/	13631
UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E118976
EAC			RU C- DE.AI30.B.01102

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>