


Solenoid coil

VACC-S13-18-A1-1U

Part number: 562890

FESTO

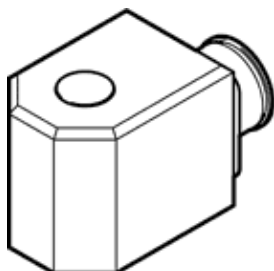

Data sheet

Feature	Value
Type of actuation	electrical
Assembly position	Any
Switching position indicator	No
Duty cycle	100%
Insulation class	H
Characteristic coil data	24 V DC: 1.8 W 24 V AC: 40/65 Hz, power 1.8 VA
Permissible voltage fluctuation	-15 % / +10 %
Corrosion resistance classification CRC	4 - Very high corrosion stress
Protection class	IP65
Ambient temperature	-20 ... 60 °C
Product weight	210 g
Electrical connection	Plug to EN 175301-803 Plug pattern type A to EN 175301-803
Materials note	Contains PWIS substances Conforms to RoHS
Material solenoid coil	PA UP