


Supply plate VMPA-FB-SP-7/8-V-4POL

Part number: 541084

FESTO

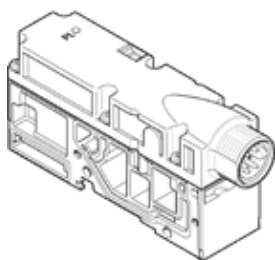

Data sheet

Feature	Value
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 25 %
Corrosion resistance classification CRC	1 - Low corrosion stress
Protection class	IP65
Ambient temperature	-5 ... 50 °C
Authorization	c UL us - Recognized (OL)
Product weight	200 g
Electrical connection	7/8" round plug connector 4-pin
Materials note	Conforms to RoHS
Material cover	PA-reinforced
Material housing	Aluminum die cast