


# Solenoid coil

## VACC-S18-120-A1-2A

Part number: 8040582

FESTO

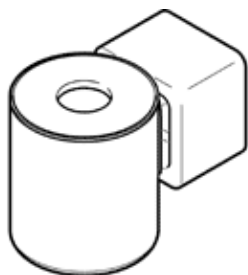

### Data sheet

Feature	Value
Type of actuation	electrical
Assembly position	Any
Switching position indicator	No
Duty cycle	100%
Insulation class	H
Characteristic coil data	110 V AC: 50/60 Hz, power: 12 VA
Permissible voltage fluctuation	-15 % / +10 %
CE symbol (see declaration of conformity)	according to EU low voltage guideline
Corrosion resistance classification CRC	4 - Very high corrosion stress
Protection class	IP65
Ambient temperature	-20 ... 60 °C
Product weight	530 g
Electrical connection	Plug to EN 175301-803 Plug pattern type A to EN 175301-803
Materials note	Contains PWIS substances Conforms to RoHS
Material solenoid coil	PA Steel