

Cable connector - UC-63P1N1280DU - 1606777

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Cable connector, straight, shielded: yes, Screw locking, M23, Number of positions: 6+3, Type of contact: Male connector, Solder connection

The figure shows the 12-pos. product version



Key Commercial Data

Packing unit	1 STK
Custom tariff number	85366990
Country of origin	Germany


Technical data

Product type	Circular connector (cable-side)
Approval	EAC
Coding	N
Type	Cable connector
Number of positions	9
Thread	M23
Rated voltage (IEC)	150
Rated current (IEC)	20
Knurl material	Metal
Shielding	yes
Signal type	Signal
Connection method	Solder connection


Drawings

Cable connector - UC-63P1N1280DU - 1606777

Schematic diagram

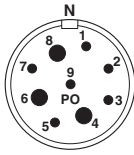

Dimensional drawing

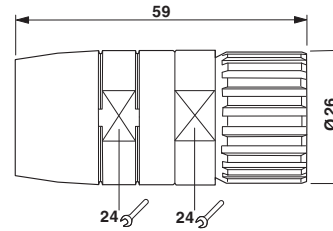

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260708
eCl@ss 7.0	27440312
eCl@ss 8.0	27440102
eCl@ss 9.0	27440103

ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC002635
ETIM 5.0	EC002635

UNSPSC

UNSPSC 6.01	43172015
UNSPSC 7.0901	43201404
UNSPSC 11	43172015
UNSPSC 12.01	43201404
UNSPSC 13.2	43201404

Approvals

Approvals

Approvals

EAC

Cable connector - UC-63P1N1280DU - 1606777

Approvals

Ex Approvals

Approval details

EAC B.01742
