


RJ45 connector - CUC-V06-C1PBK-S/R4CE8:1 - 1414408

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 028309
GTIN	4055626028309

Technical data

Mechanical characteristics

Number of positions	8
Connection profile	RJ45
Insertion/withdrawal cycles	≥ 750
Connection method	Crimp connection
Type of contact	Crimp contacts
Conductor cross section	0.1 mm ² ... 0.2 mm ² (flexible)
Connection cross section AWG	24 ... 27 (flexible)
External cable diameter	5 mm ... 8.5 mm
Cable outlet	straight
Color	black
Degree of protection	IP67
Type	RJ45, IP67, version 6
No. of cable outlets	1

Ambient conditions

Ambient temperature (operation)	-25 °C ... 60 °C
---------------------------------	------------------

Material data

Flammability rating according to UL 94	V0
--	----

RJ45 connector - CUC-V06-C1PBK-S/R4CE8:1 - 1414408

Technical data

Material data

Housing material	PA
Contact carrier material	PC
Contact material	Phosphor bronze
Contact surface material	Gold
O-ring material	FPM
Cable seal material	NBR

Electrical characteristics

Number of positions	8
Nominal voltage U_N	72 V (DC)
Nominal current I_N	1.75 A
Transmission characteristics (category)	CAT6
GRP transmission properties	CAT6
Transmission speed	1 Gbps (250 MHz)
Frequency range	to 250 MHz
Rated current	1 A
Overvoltage category	I
Degree of pollution	2
Rated voltage (III/3)	72 V (DC)

Standards and Regulations


Flammability rating according to UL 94	V0
--	----

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"


Drawings

Dimensional drawing

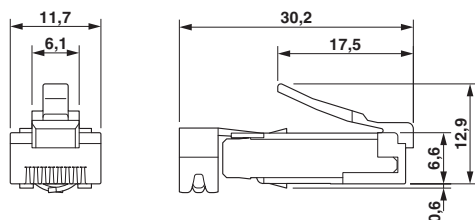

RJ45 male insert

Dimensional drawing

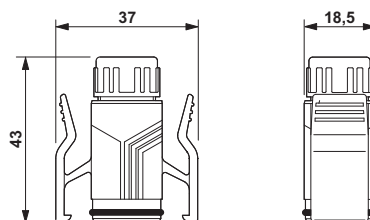

RJ45 sleeve housing IP67

Approvals

Approvals

RJ45 connector - CUC-V06-C1PBK-S/R4CE8:1 - 1414408


Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		B.01742
-----	---	---------

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>