

## Crimping pliers - CRIMPFOX 16R TWIN - 1212845


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Crimping pliers, for TWIN ferrules according to UL 486F, three marked die stations, unlockable pressure lock, lateral entry

### Why buy this product

- Ergonomically designed handles ensure an optimum grip and reduce the amount of force required by 25%

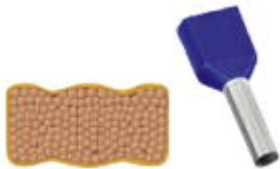

### Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 406220
GTIN	4055626406220

### Technical data

#### Dimensions

Length (b)	256 mm
Width (a)	25 mm
Height (c)	68 mm

#### General

Color	black
Compression	WM crimp
Type of contact	TWIN ferrules
Weight	578 g
Min. cross section	6 mm <sup>2</sup>
Max. cross section	16 mm <sup>2</sup>

### Approvals

Approvals

## Crimping pliers - CRIMPFOX 16R TWIN - 1212845

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

### Approval details

EAC



RU x-  
DE.xx08.B.02974

---

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG

Flachsmarktstr. 8

32825 Blomberg

Germany

Tel. +49 5235 300

Fax +49 5235 3 41200

<http://www.phoenixcontact.com>