


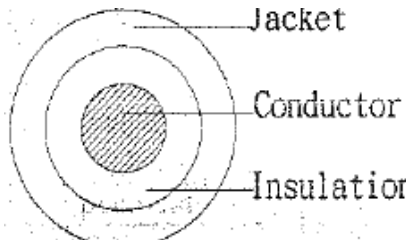

Datasheet

Product Name:	UL1385 22AWG
Product Discription:	UL1385 22AWG
Specification No.:	SPEC-UL1385-22AWG
Customer's Name:	

Description		Construction					
Rated Voltage:	No voltage rating	Conductor	Stranded Tinned Copper				
Rated Temperature:	125°C	Size(AWG)	22				
Reference Standard:	UL758	Construction(±0.004mm)	17/0.16				
Cross Section 		Stranded Dia.(mm)Ref.	0.76				
		Insulation Material	XL-PE		Jacket Material	XL-PVDF	
		Insulation Color	White		Jacket Color	Any color	
		Ave Thickness(mm)	0.15		Ave Thickness(mm)	0.10	
		Min Thickness(mm)	0.12		Min Thickness(mm)	0.08	
		Insulation Dia.(±0.10mm)	1.10		Jacket Dia.(±0.10mm)	1.3	

Marking		Characteristics				Customer Approve
No cable marking		Remark: 8918772 Red 8918776 Blue 8918794 Grey 8918798 Violet 8918760 Black 8918785 White 8918782 Yellow 8918779 Brown 8918788 Green 8918791 Orange				Seal & Stamp Signature: Date:
Applications		Test Item		Standard Value		
Internal wiring of electronic equipment.		Test Material		XLPE and XLPVDF(ROHS)		
		Insulation resistance(20°C MΩ/KM)		0.75		
		Vol. Tesr(AC.V.60S) (V)		500		
		Flammability Test		Horizontal flame		
		Max.DC Resistance(20°C Ω/km)		59.4(MAX)		

Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	YanBin	Jason	10/08/2015