

Housing - HC-STA-D15-BWSC-EL-AL - 1424363

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Panel mounting base D15, with single locking latch, material: Die-cast aluminum, salt water resistant, protective cover material: PA, height: 26 mm, cable gland: none, support sleeve: no, protective cover: yes, Standard



Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4055626371054

Technical data

Dimensions

Height	26 mm
Width	39 mm
Length	82 mm
Length of the assembly cutout	58 mm
Width of the assembly cutout	24 mm

Ambient conditions

Degree of protection of housing (IP)	IP66 ()
	IP67 (when plugged in)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Note	For contact inserts HC-D15, A10
Size	D15
Housing type	Panel mounting base
Color	gray aluminum
Locking type	with single locking latch
Screw connection	none
Protective cover	yes

Housing - HC-STA-D15-BWSC-EL-AL - 1424363

Technical data

General


Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated
Material lock	PA
Material, protective cover	PA

Environmental Product Compliance


China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Dimensional drawing

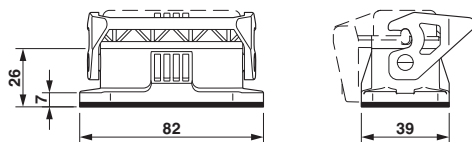

Dimensional drawing

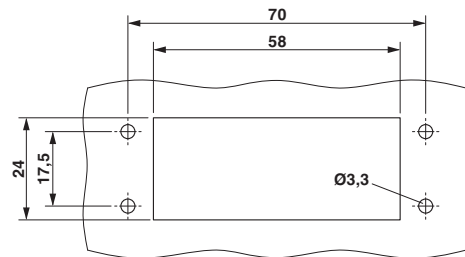

Dimensional drawing

Mounting cutout

Approvals

Approvals

Approvals

EAC / GL

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	--	---------------

GL		http://exchange.dnv.com/tari/	6196614 HH
----	--	---	------------

Phoenix Contact 2018 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>