

## DIN rail perforated - NS 15 PERF 1000MM - 1207646


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



DIN rail perforated, Standard profile, width: 15 mm, height: 5.5 mm, acc. to EN 60715, material: Steel, galvanized, passivated with a thick layer, length: 1000 mm, color: silver

RoHS

### Key Commercial Data

Packing unit	20 pc
Minimum order quantity	20 pc
GTIN	 4 046356 366045
GTIN	4046356366045

### Technical data

#### Dimensions

Height	5.5 mm
Length	1000 mm
Width	15 mm
Hole width	12.20 mm
Hole height	4.20 mm
Drill hole spacing	20.00 mm

#### General

Material	Steel
Coating	galvanized, passivated with a thick layer
Color	silver

#### Standards and Regulations

Test standard	acc. to EN 60715
Connection in acc. with standard	IEC / EN

#### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
------------	---

# DIN rail perforated - NS 15 PERF 1000MM - 1207646


## Technical data

### Environmental Product Compliance

No hazardous substances above threshold values
--

## Drawings

Dimensional drawing

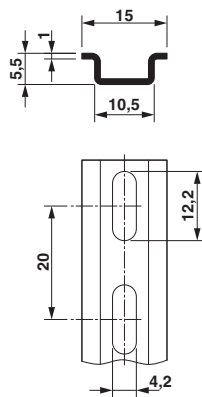

---

Phoenix Contact 2018 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>