




BURNDY Catalog Number
UPC Number
Description
Status

PAT60018V
 7818103612766
 PAT600 W/18V BATTERY SYS
 Active

Web Use
 BURNDY Product Line

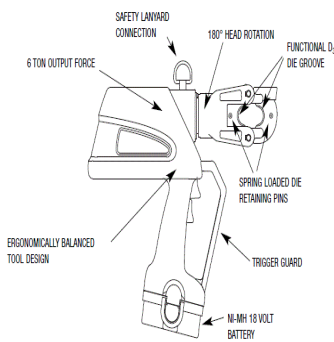

Dimensional	
Width (in)	3.5
Length (in)	14.5
Height (in)	13.75

General	
Weight lbs	10.9
Warranty	5 years on tool; 1 year on battery and charger; Lifetime on INFINITY DRIVE® #174;
Product Description	Battery Actuated Tool, Hydraulic self-Contained, 6 Ton, 18V Ni-MH

Approvals / Certifications	
ROHS Compatible	Exempt
CULUS	N

Physical	
Pressure (Operating)	7800
Crimp Force	6 tons (5.4 metric tons)
Force Developed	6 tons
Operating Voltage	18 VDC

Documentation

Literature

- [NI-MH18Vand14VMAKITABATTERYMSDS](#)

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175