




BURNDY Catalog Number
UPC Number
Description
Status

PAT4PC834LI
 7818105054411
 4-POINT(R) C HEAD LI
 Active

Web Use
 BURNDY Product Line

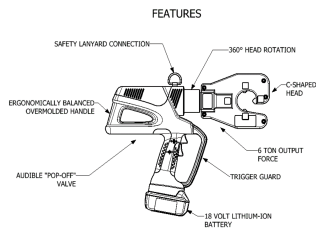

Dimensional

Width (in) 3.7
 Length (in) 17.6
 Height (in) 13.9

General

Weight lbs 13
 Warranty 5 years on tool; 1 year on battery and charger; Lifetime on INFINITY DRIVE®
 Product Description 4 Point C-Head Dieless Tool, Hydraulic, 6 Ton, 18V Lithium Ion

Approvals / Certifications

ROHS Compatible Exempt
 CULUS N

Physical

Pressure (Operating) 7800
 Crimp Force 6 tons (5.4 metric tons)
 Force Developed 6 tons
 Operating Voltage 18 VDC

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175