



**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

Y35BH  
 7818104084522  
 REMOTE POWER OPERATED  
 CRIMPING TOOL HEAD  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Width (in) 4.75  
 Height (in) 9.75

**General**


Warranty 5 Year Limited  
 Weight lbs 8  
 Product Description Remote Power Operated Crimping Tool Head, 12 Ton, 10000 psi, 8 AWG(Sol) - 750 kcmil Copper, 6 AWG(Sol) - 750 kcmil Aluminium, U Dies

**Approvals / Certifications**

ROHS Compatible Exempt  
 CULUS N

**Physical**

Pressure (Operating) 10,000  
 Crimp Force 12 tons  
 Jaw Opening .95"  
 Covered Head N  
**Documentation**

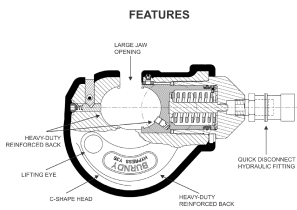

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175