



BURNDY Catalog Number
UPC Number
Description
Status

Y35
 7818104084077
 CRIMPER, 12 TON, C-HEAD
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 4.75
 Height (in) 23.25

General

Warranty 2 Year Limited
 Weight lbs 13
 Self Contained Hydraulic Crimping Tool, 12 Ton Output Force, 10000 psi, 8 AWG-750 kcmil, 8 AWG-750 kcmil Aluminium, Up to 3/4" Ground Rod, U Dies


Product Description

Approvals / Certifications

ROHS Compatible Exempt
 CULUS N

Physical

Pressure (Operating) 10000
 Type of Dies U
 Crimp Force 12 tons
 Jaw Opening .95
 Covered Head N
Documentation

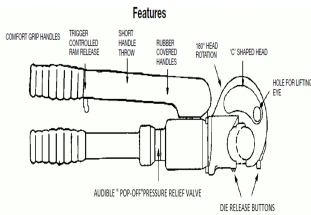

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175