




**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

YGL34C29  
 7818102200477  
 250-500 TO 2-250 GRD GRI  
 Active



**Web Use**  
 BURNDY Product Line

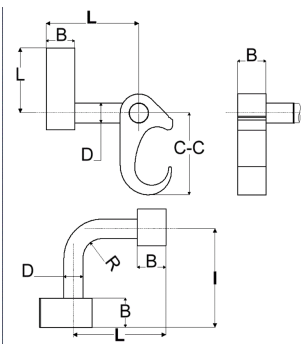

Length (in)  
 B Length (in)

**Dimensional**  
 2.50  
 0.75

Product Description

**General**  
 Copper Compression Cross Grid  
 Connector, 250 kcmil - 500 kcmil  
 or 5/8" - 3/4" Ground Rod or # 5 -  
 6 Rebar, 2 AWG (Str.) - 250 kcmil  
 Y

Prefilled (Oxide Inhibitor)

**Other**  
 Penetrox E

Type of Oxide Inhibitor

**Approvals / Certifications**

Rated for Direct Burial  
 UL Listed  
 CSA Certified  
 ROHS Compatible  
 UL Recognized  
 CULUS  
 Industry Standards

Y  
 Y  
 Y  
 Compliant  
 N  
 N  
 UL467,IEEE 837

Rod Size (Side A) - Range  
 Rod Size (Side B) - Range  
 Rebar Size (Side B) - Range  
 Copper Solid Size (Side A) - Range  
 Copper Str Size(Side B) - Range  
 Copper Str Size (Side A) - Range  
 CopperSolid Size (Side B) - Range  
 Rebar Size (Side A) - Range

**Conductor(s)**  
 5/8 in-3/4 in  
 N/A  
 N/A  
 N/A  
 2 AWG-250 kcmil  
 250 kcmil-500 kcmil  
 N/A  
 5 -6

Type of Plating  
 Plated (Yes or No)  
 Index Number  
 Product Material

**Physical**  
 Unplated  
 N  
 997,998  
 Copper

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175