

KombiSIGN 70 / Audible Devices 844
Siren element 8 tne 24VAC/DC BK



| | |
|-----------|--------------|
| Part No.: | 844.126.55 |
| Series: | KombiSIGN 70 |




| MECHANICAL DATA | |
|-----------------------------|-----------------|
| Height | 72 mm |
| Diameter | 70 mm |
| Materials | PC |
| Housing colour | Black |
| Protection category | IP54 |
| Service life optical | 5,000 h minimum |
| Acoustic service life | 5,000 h minimum |
| Working temperature minimum | -20°C |
| Working temperature maximum | +50°C |
| Weight with packaging | 107 g |
| Product weight | 92 g |

| ELECTRICAL DATA | |
|---------------------------|--------|
| Operating voltage | 24V |
| Operating voltage type | AC/DC |
| Rated operational current | 80 mA |
| Rated inrush current | 200 mA |

| ACUSTICAL DATA | |
|-------------------------------|------------|
| Volume/dB(max) at 1m distance | 100 dB(A) |
| Acoustic signal image | Multi-tone |
| Number of tones | 8 tone |

DRAWING

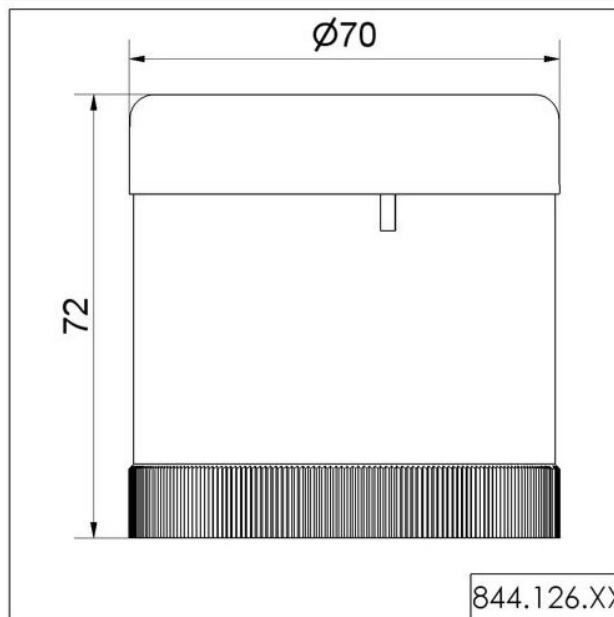

! For additional installation and mounting information, refer to the appropriate user guide at www.werma.com. This printed copy is for information only and is subject to alteration.