








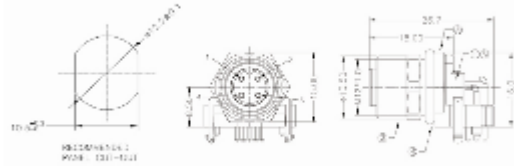

# PXMBNI12RAM08APCM12 Datasheet

Product Name // PXMBNI12RAM08APCM12

 [View Product Page](#)



## // Product Description:

-  Material=Metal
-  Pins=8
-  Max Rating=30Vac
-  Ingress Protection=IP68
-  Operating Temperature= -25Å°C to +85Å°C
-  Contact Resistance=5? max.
-  Insulation Resistance=>100M?
-  Mechanical Cycles=100 (min)

## // General Information:

Product Display Title:	M12 Right Angle Rear Panel Mount
Product Family:	Circular Automation Connectors
Product Series:	M12 Series
Body Material:	Brass - Nickel Plated
Contact Type:	Plug Contact
Number Of Contacts:	8 Contacts

### // Product PDF Links

 [M12 Series automation connectors...](#)

### // Product 3D CAD Model Links

 [PXMBNI12RAM08APCM123D CAD Model](#)