

## FEATURES

- Pozidriv head type for improved screwdriver grip
- Pan head design for a flat bearing surface
- A4 316 Marine Grade stainless steel
- Easily cleanable
- Meets DIN 7985 Standards

## RS PRO, M3 Pan Head, 6mm Stainless Steel Pozidriv A4 316

RS Stock No.: 190-428



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description


From RS PRO a high-quality pan head machine screw with a versatile Pozidriv recess for a superior grip when tightening. This machine screw has a metric thread and is made from high quality A4 stainless steel which has excellent corrosion resistance. Grade 316 steel is also known as marine grade stainless steel due to its increased resistance to chloride corrosion making it ideal for use in marine applications.

### General Specifications

<b>Head Shape</b>	Pan
<b>Drive Type</b>	Cross
<b>Applications</b>	Swimming pools, Chemical plants, Boat deck fittings, Dairy equipment, Medical sterilising equipment, Sewerage treatment plants

### Mechanical Specifications

<b>Thread Size (Metric)</b>	M3
<b>Length Metric</b>	6mm
<b>Material</b>	Stainless Steel
<b>Stainless Steel Type</b>	A4 316
<b>Finish</b>	Plain
<b>Thread Pitch</b>	0.5mm
<b>Specification</b>	DIN 7985

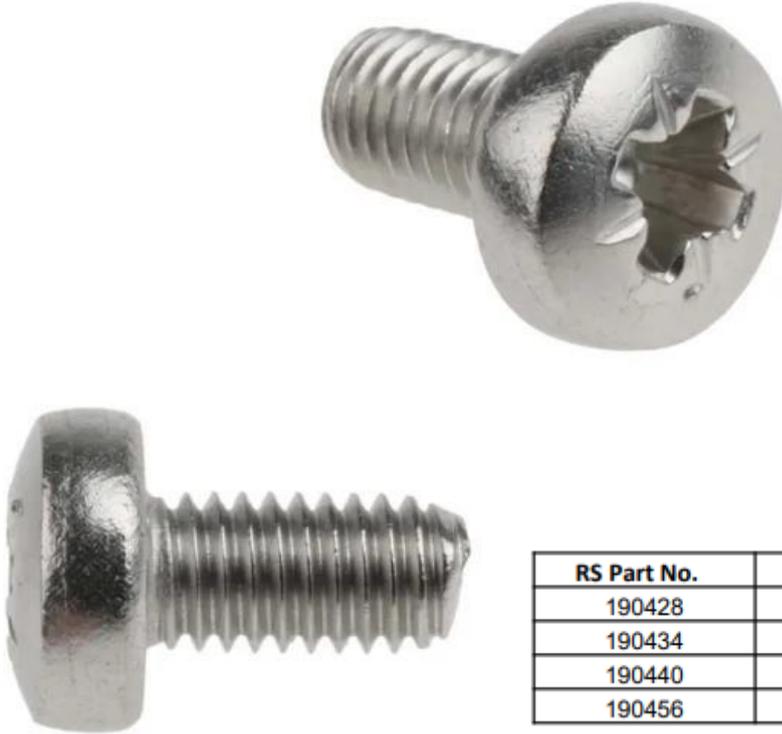

RS Part No.	Thread Size	Length
190428	M3	12mm
190434	M3	8mm
190440	M3	10mm
190456	M3	12mm

