

FEATURES

- CAT 5E
- Punch Down
- Krone Style
- Colour Coded
- White

RS PRO CAT 5E White Punch Down Ethernet Coupler

RS Stock No.: 2662257



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

CAT 5E Punch down Krone coupler in white for connecting Cat5e cables, suitable for solid Cat5 and colour coded for easy installation.

General Specifications

| | |
|-----------------------------|--------------------|
| Type | Punch Down Coupler |
| Interface Type | RJ45 Female |
| LAN Category | Cat 5E |
| Number of Ports | 2 |
| Shield Type | UTP |
| Wiring Configuration | Straight Through |
| Colour | White |
| Contact plating | Gold |
| Housing Material | PVC |
| Packaging | 1 |
| Compatible Networks | 100Mbps/10Mbps |
| Number of Conductors | 8 |

Mechanical Specifications


| | |
|---------------|---------|
| Length | 30mm |
| Width | 25mm |
| Depth | 25mm |
| Weight | 0.023KG |

Approvals

| | |
|----------------------------------|--------------------|
| Compliance/Certifications | CE UKCA ROHS REACH |
| Declarations | CE UKCA ROHS REACH |

Similar Products

| Parameters | 2662258 | 2662260 | 2662259 |
|----------------------|--------------------|--------------------|--------------------|
| Type | Punch Down Coupler | Punch Down Coupler | Punch Down Coupler |
| Colour | Black | White | Black |
| Interface Type | RJ45 Female | RJ45 Female | RJ45 Female |
| LAN Category | CAT 5E | CAT 6 | CAT 6 |
| Number of Ports | 2 | 2 | 2 |
| Shield Type | N/A | N/A | N/A |
| Wiring Configuration | Straight Through | Straight Through | Straight Through |

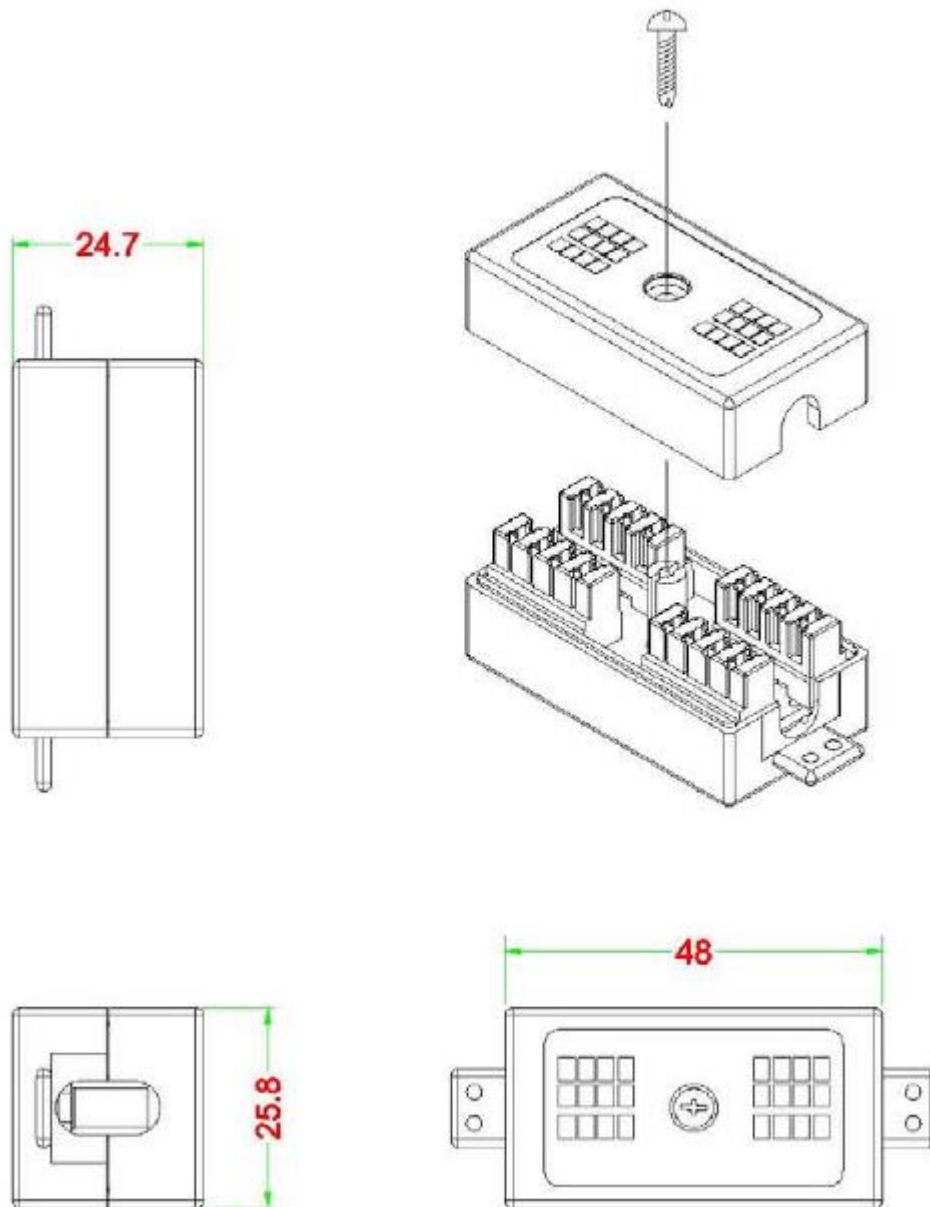

Performance:

Meets C5e EIA/TIA 568B Standard.

Materials:

Body : Fireproof ABS UL-94V0

PCB : FR-4 / UL-94V0

IDC Body : Fireproof ABS UL-94V0

IDC Pin : Bronze & Tinned

IDC Description : For 22-26 AWG.

For 110 or Krone punch-down Tool

Electrical Specifications:

Insulation Resistance : 500M ohms (min.)

Contact Resistance : 20m ohms (max.)

Current Rating : 1.5 Amps

DC Resistance : 0.1 ohms (max.)

Withstanding Voltage : 1000 VAC RMS @ 60Hz / 1 min.

Mechanical Specifications:

IDC Punch Down Cycle : Over 250 cycles

Operation Temperature : -40 °C ~ +70 °C