

FEATURES

- CAT 5E
- Punch Down
- Krone Style
- Colour Coded
- Black

RS PRO CAT 5E Black Punch Down Ethernet Coupler

RS Stock No.: 2662258



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

CAT 5E Punch down Krone coupler in black for connecting Cat5e cables, suitable for solid Cat5 and colour coded for easy installation.

General Specifications

Type	Punch Down Coupler
Interface Type	RJ45 Female
LAN Category	Cat 5E
Number of Ports	2
Shield Type	UTP
Wiring Configuration	Straight Through
Colour	Black
Contact plating	Gold
Housing Material	PVC
Packaging	1
Compatible Networks	100Mbps/10Mbps
Number of Conductors	8

Mechanical Specifications


Length	30mm
Width	25mm
Depth	25mm
Weight	0.023KG

Approvals

Compliance/Certifications	CE UKCA ROHS REACH
Declarations	CE UKCA ROHS REACH

Similar Products

Parameters	2662257	2662260	2662259
Type	Punch Down Coupler	Punch Down Coupler	Punch Down Coupler
Colour	White	White	Black
Interface Type	RJ45 Female	RJ45 Female	RJ45 Female
LAN Category	CAT 5E	CAT 6	CAT 6
Number of Ports	2	2	2
Shield Type	N/A	N/A	N/A
Wiring Configuration	Straight Through	Straight Through	Straight Through

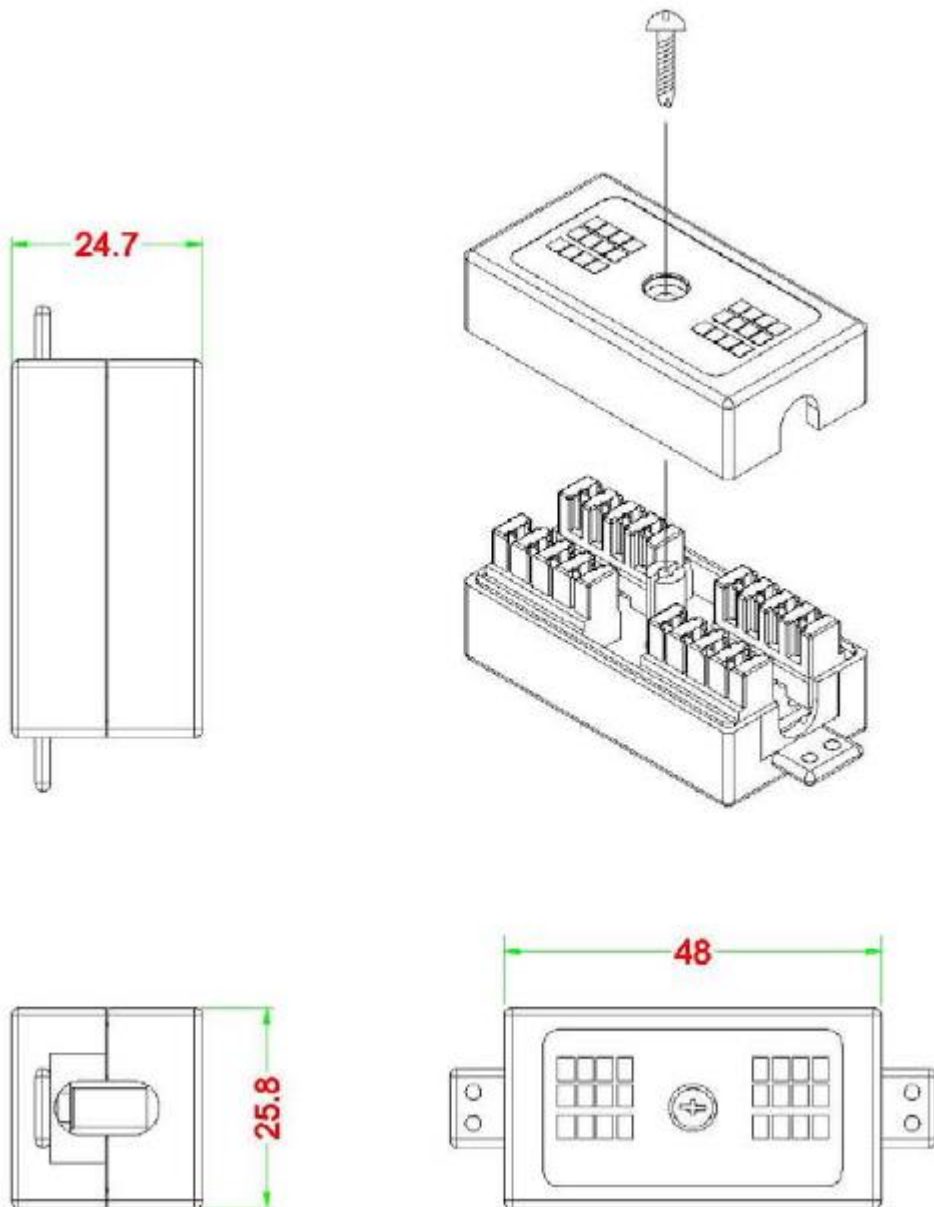

Performance:

Meets C5e EIA/TIA 568B Standard.

Materials:

Body : Fireproof ABS UL-94V0

PCB : FR-4 / UL-94V0

IDC Body : Fireproof ABS UL-94V0

IDC Pin : Bronze & Tinned

IDC Description : For 22-26 AWG.

For 110 or Krone punch-down Tool

Electrical Specifications:

Insulation Resistance : 500M ohms (min.)

Contact Resistance : 20m ohms (max.)

Current Rating : 1.5 Amps

DC Resistance : 0.1 ohms (max.)

Withstanding Voltage : 1000 VAC RMS @ 60Hz / 1 min.

Mechanical Specifications:

IDC Punch Down Cycle : Over 250 cycles

Operation Temperature : -40 °C ~ +70 °C