

# LED Designer Deco

## 5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20

Philips LED Designer Deco lamps allow you to maintain a warm, classic light or a modern, chic effect while providing longer life and energy savings

### Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	15,000 hour(s)
Switching Cycle	20,000
Lighting Technology	LED
EU RoHS compliant	Yes

Light Technical	
Color Code	950 [CCT of 5000K]
Beam Angle (Nom)	330 degree(s)
Luminous Flux	500 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	90 lm/W
Color Consistency	<4
Color rendering index (CRI)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical	
Line Frequency	60 Hz
Input Frequency	60 Hz
Power Consumption	5.5 W
Lamp Current (Nom)	62 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s

Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (Nom)	120 V

Temperature	
Ambient temperature range	-4 °F to 113 °F

Controls and Dimming	
Dimmable	Only with specific dimmers

Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Glass
Bulb Shape	ST19
UL Wet/ damp/ dry location	Wet location

Approval and Application	
Energy Certifications	Energy Star
T20 compliant	Yes

Application Conditions	
can it be used in closed luminaires	No


Product Data	
Order product name	5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20

# LED Designer Deco

Full product name	5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20
Order code	565812
Material Nr. (12NC)	929002988803
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677565817


Numerator - Packs per outer box	4
EAN/UPC - Case	50046677565812

## Dimensional drawing

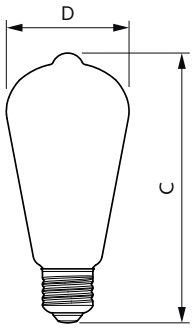


Product	D	C
5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20	2-9/16 inch	5-7/16 inch

## Photometric data

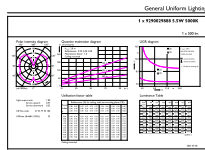


General Uniform Lighting - 5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20

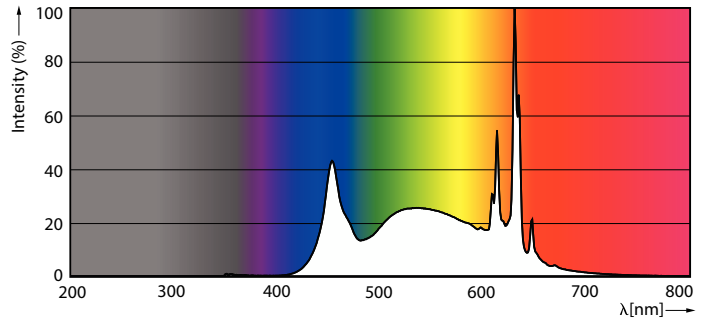

Spectral Power Distribution Colour

General uniform lighting - 5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20

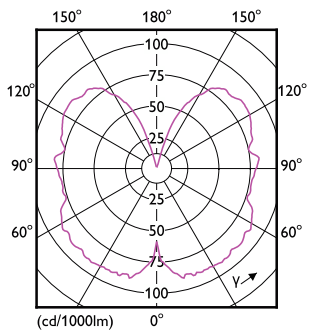

Light Distribution Diagram - 5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20

## Lifetime



Life Expectancy Diagram - 5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20

Lumen Maintenance Diagram - 5.5ST19/VIN/950/E26/CL/G/SP D 4/1PF T20

