



Classic filament LEDbulbs

12A19/LED/930/FR/Glass/E26/DIM 1FB T20

Philips LED vintage-style lamps allow you to maintain a warm, classic light effect while providing longer life and energy savings.

Product data


General Information		Lamp Current (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]		105 mA
Nominal lifetime	15,000 hour(s)	Wattage Equivalent	100 W
Switching Cycle	20,000	Starting Time (Nom)	0.5 s
Lighting Technology	LED	Warm-up time to 60% light	0.5 s
EU RoHS compliant	Yes	Power Factor (Fraction)	0.7
		Voltage (Nom)	120 V
Light Technical		Temperature	
Color Code	930 [CCT of 3000K]	Ambient temperature range	-4 °F to 113 °F
Beam Angle (Nom)	320 degree(s)		
Luminous Flux	1,600 lm	Controls and Dimming	
Color Designation	White (WH)	Dimmable	Only with specific dimmers
Correlated Color Temperature (Nom)	3000 K		
Luminous Efficacy (rated) (Nom)	133.00 lm/W	Mechanical and Housing	
Color Consistency	<4	Bulb Finish	Frosted
Color rendering index (CRI)	90	Bulb Material	Glass
LLMF At End Of Nominal Lifetime (Nom)	70 %	Bulb Shape	A19 [A 19mm]
		UL Wet/ damp/ dry location	Wet location
Operating and Electrical		Approval and Application	
Line Frequency	60 Hz	Energy Certifications	Energy Star
Input Frequency	60 Hz		
Power Consumption	12 W		

Classic filament LEDbulbs

T20 compliant	Yes
Application Conditions	
can it be used in closed luminaires	Yes
Product Data	
Order product name	12A19/LED/930/FR/Glass/E26/DIM 1FB T20
Full product name	12A19/LED/930/FR/Glass/E26/DIM 1FB T20



Order code	578625
Material Nr. (12NC)	929003498304
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677578626
Numerator - Packs per outer box	10
EAN/UPC - Case	50046677578621

Dimensional drawing

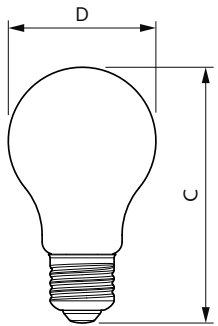


Product	D	C
12A19/LED/930/FR/Glass/E26/DIM 1FB T20	2-5/8 inch	4-9/16 inch

Photometric data

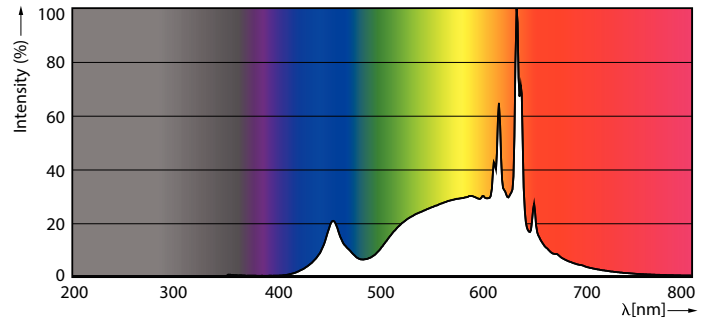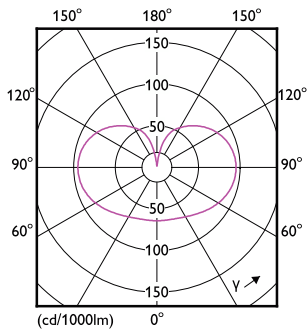

Light Distribution Diagram - 12A19/LED/930/FR/Glass/E26/DIM 1FB T20

Spectral Power Distribution Colour - 12A19/LED/930/FR/Glass/E26/DIM 1FB T20

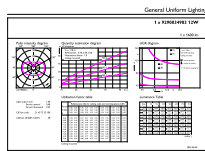

General uniform lighting - 12A19/LED/930/FR/Glass/E26/DIM 1FB T20

Classic filament LEDbulbs

Lifetime



Life Expectancy Diagram - 12A19/LED/930/FR/Glass/E26/DIM 1FB T20

Lumen Maintenance Diagram - 12A19/LED/930/FR/Glass/E26/DIM 1FB T20

